


3.3 Display Module 4 x 40 LCD

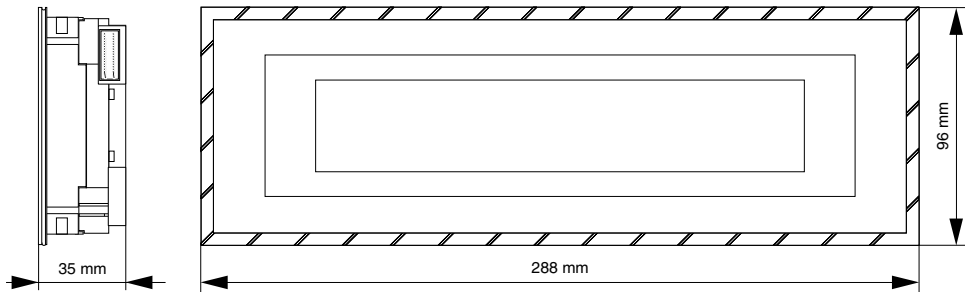

Technical Data	
Model Number	
Blue	4D1044-00-090
Black	4D1044-00-590
Display Type	LCD
Lines x Characters	4 x 40
Character Height	4.3 mm
Background Lighting	LED
Color	Black on yellow
Temperature	
Operating	0 to 50 °C (32 to 122 °F)
Storage	-20 to 60 °C (-4 to 140 °F)
Relative Humidity	
Operating	10 to 90 % (non-condensing)
Storage	10 to 90 % (non-condensing)
Shock	Conforms to IEC 60068-2-27 15g equivalent, 150 m/sec ² , 11 msec, 3 axes (positive and negative)
Vibration	Conforms to IEC 60068-2-6 1g equivalent, 10-58 Hz; 0.075 mm 58-150 Hz; 9.8m/sec ² 20 cycles per axis
Current Requirements	155 mA at 24 VDC